

REV. 1


DCO 15943

COIL: @ 25°C	
RESISTANCE	310 OHMS ±10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	5.6 VDC
MUST RELEASE	0.55 VDC

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 20 g's
SHOCK	50 g's 11 ±1 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	OPERATE 6 MS MAX
	RELEASE 5 MS MAX
	CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

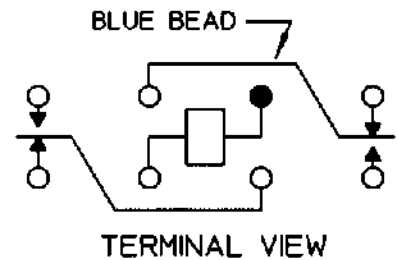

CONTACT RATING: LOW LEVEL TO 2A  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 11/30/95 CK. GAH 11/22/99

COMMUNICATIONS  
INSTRUMENTS, INC.

CUST. C. I. I. STD.  
CUST. NO. REV.

\*HMS\* RELAY

HMS1201S003