


TOL = ± .010

REV. 2 1/20/98

COIL: @ 25°C	
RESISTANCE	200 OHMS ± 10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	13.0 VDC
MUST RELEASE	10.1 VDC MAX, 2.3 VDC MIN.

CUSTOMER DATA SHEET

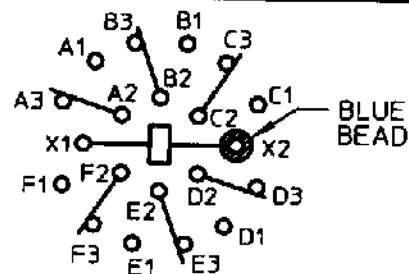

ENVIRONMENT:

VIBRATION	10 Hz TO 2000 Hz @ 20 g's
SHOCK	100 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

CONTACT RATING:	30 MICROAMPS
	30 MILLIVOLTS DC OR PEAK AC
	100,000 OPERATIONS MIN.

NOTES: OPERATE & RELEASE 15 MS MAX.
CONTACT BOUNCE 5 MS MAX.

DR. R.B. 8/8/90 CK/V2 JRB/gms

COMMUNICATIONS INSTRUMENTS, INC.

CUST. OPL
CUST. NO. M5757/1-021

TYPE "RD" RELAY

RD6CAH2600