
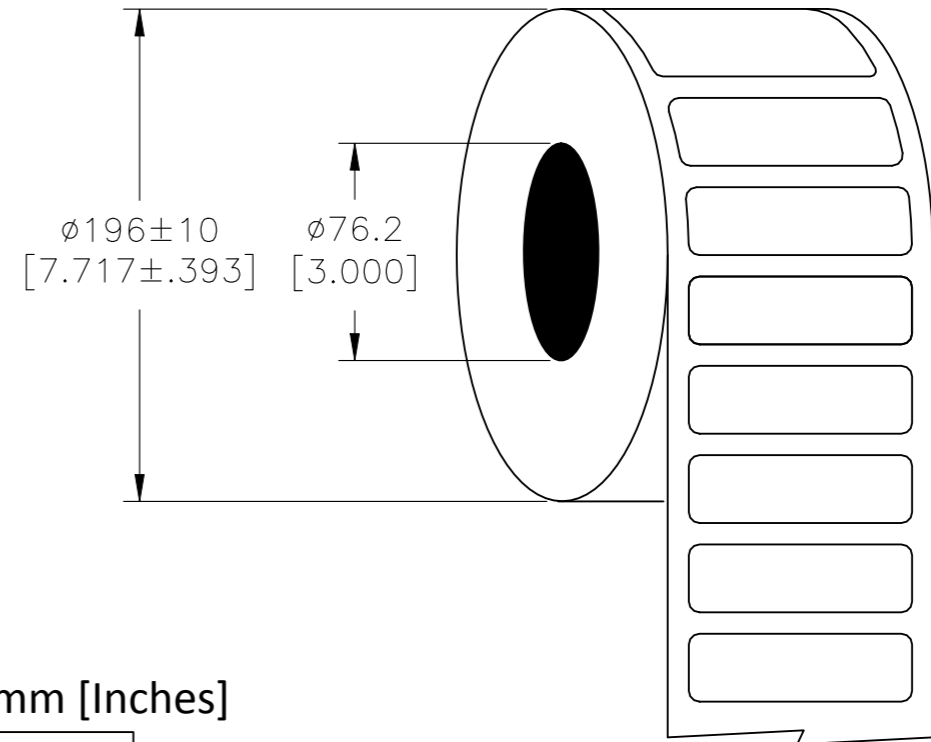


P	LTR	DESCRIPTION	DATE	DWN	APVD
	A	INITIAL RELEASE	09SEP2021	GK	DB

LABEL AND LINER DESIGN

PRESENTATION

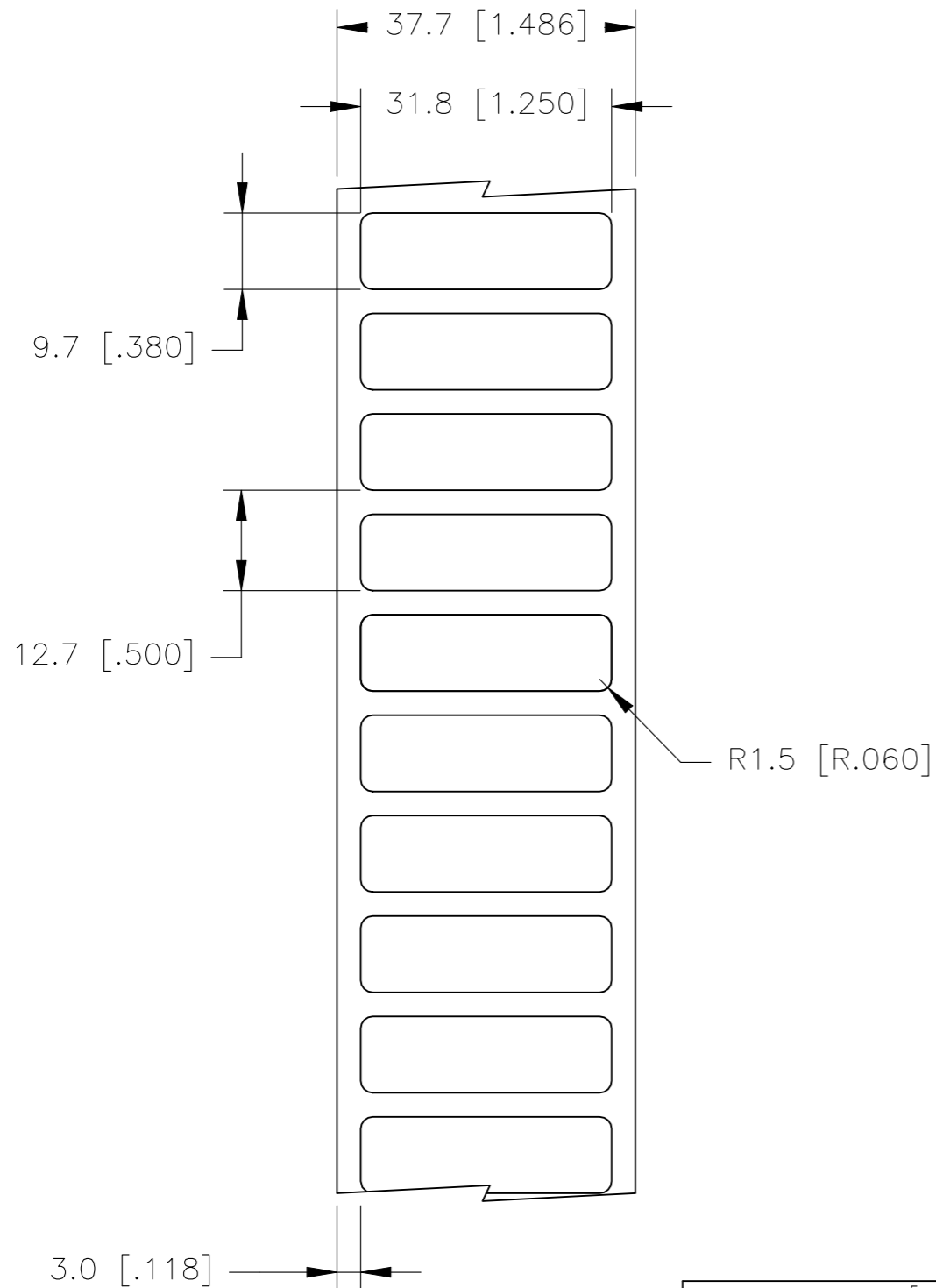

All dimensions in mm [Inches]

TE PN: A71181-000

**OUTSIDE WOUND
LABEL ACROSS: 1
PER ROLL QTY: 10000**

MATERIAL	POLYVINYL FLUORIDE (TEDLAR®)
ADHESIVE TYPE	PERMANENT ACRYLIC
LINER	BROWN KRAFT

TOLERANCES mm [INCH]	
LABEL HEIGHT:	± 0.3 [.012]
LABEL WIDTH:	± 0.3 [.012]
WEB WIDTH:	± 0.8 [.031]
VERTICAL REPEAT:	± 0.8 [.031]*
HORIZONTAL REPEAT:	± 0.8 [.031]*
PRINT POSITIONING:	± 0.8 [.031]*
LEFT MARGIN:	± 0.4 [.016]
QUANTITY:	-0 % +2 %
*NON ACCUMULATING	

THIS DRAWING IS A CONTROLLED DOCUMENT.	
DIMENSIONS: mm [INCHES]	TOLERANCES UNLESS OTHERWISE SPECIFIED:
	0 PLC $\pm -$
	1 PLC $\pm -$
	2 PLC $\pm -$
	3 PLC $\pm -$
	4 PLC $\pm -$
MATERIAL SEE TABLE	FINISH -

DWN	09SEP2021
CHK	GOPALAKRISHNA HV
APVD	09SEP2021
PRODUCT SPEC	D.BURGAT
APPLICATION SPEC	D.BURGAT
WEIGHT	0.042g

TE Connectivity	
NAME TEDLAR® LABEL - WHITE - 1 ACROSS 31.8mm x 9.7mm (1.25inch x 0.38inch)	
SIZE	RESTRICTED TO
A3	-
CAGE CODE	SCALE
FB1U7	NTS
DRAWING NO	SHEET
C-PVF-318097-10-9	1 OF 1
REV	A