
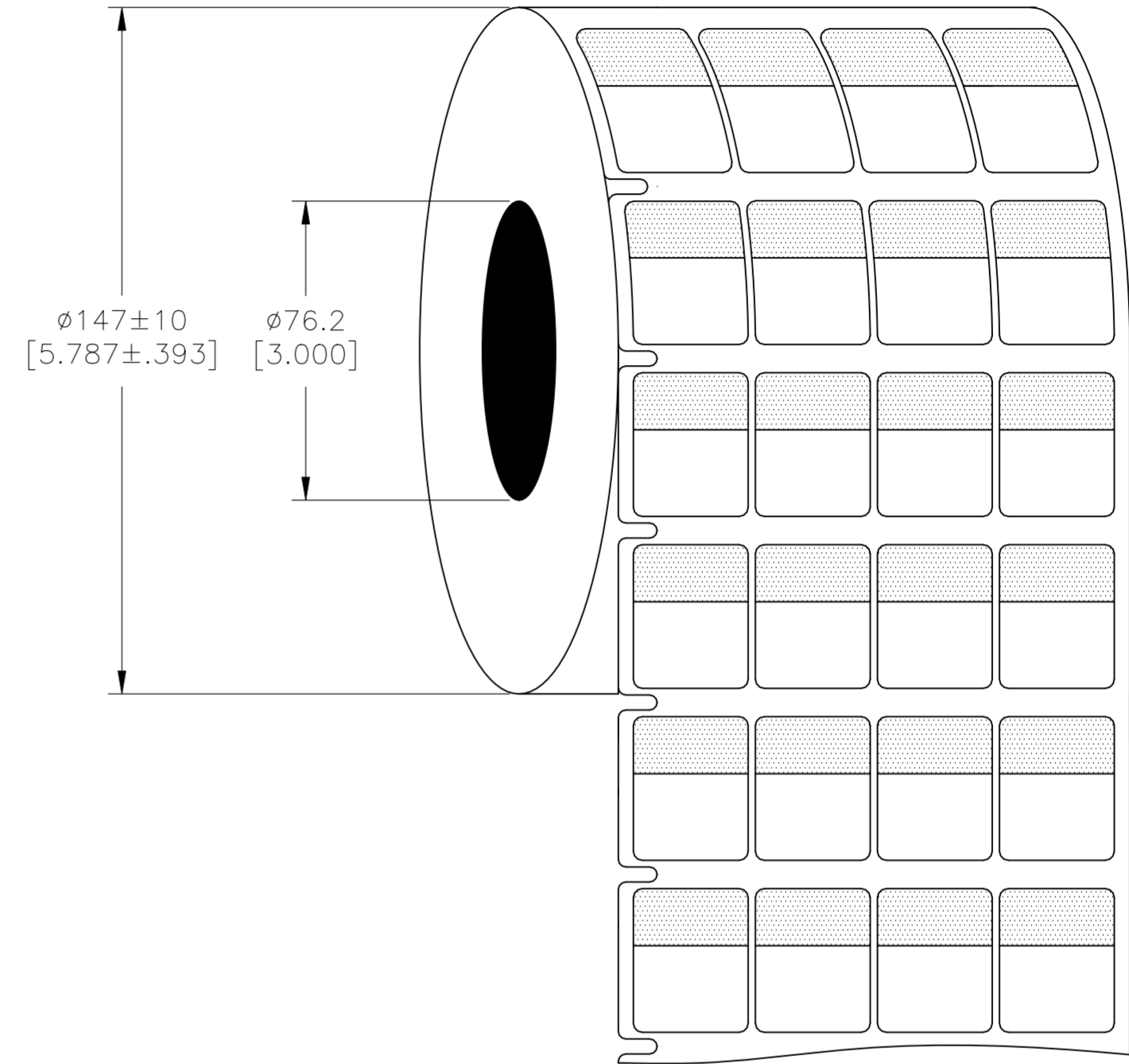


REVISIONS					
P	LTR	DESCRIPTION	DATE	DWN	APVD
F1		UL LABEL CHANGE	03JUL2024	GSK	DB

**LABEL AND LINER DESIGN**

**PRESENTATION**

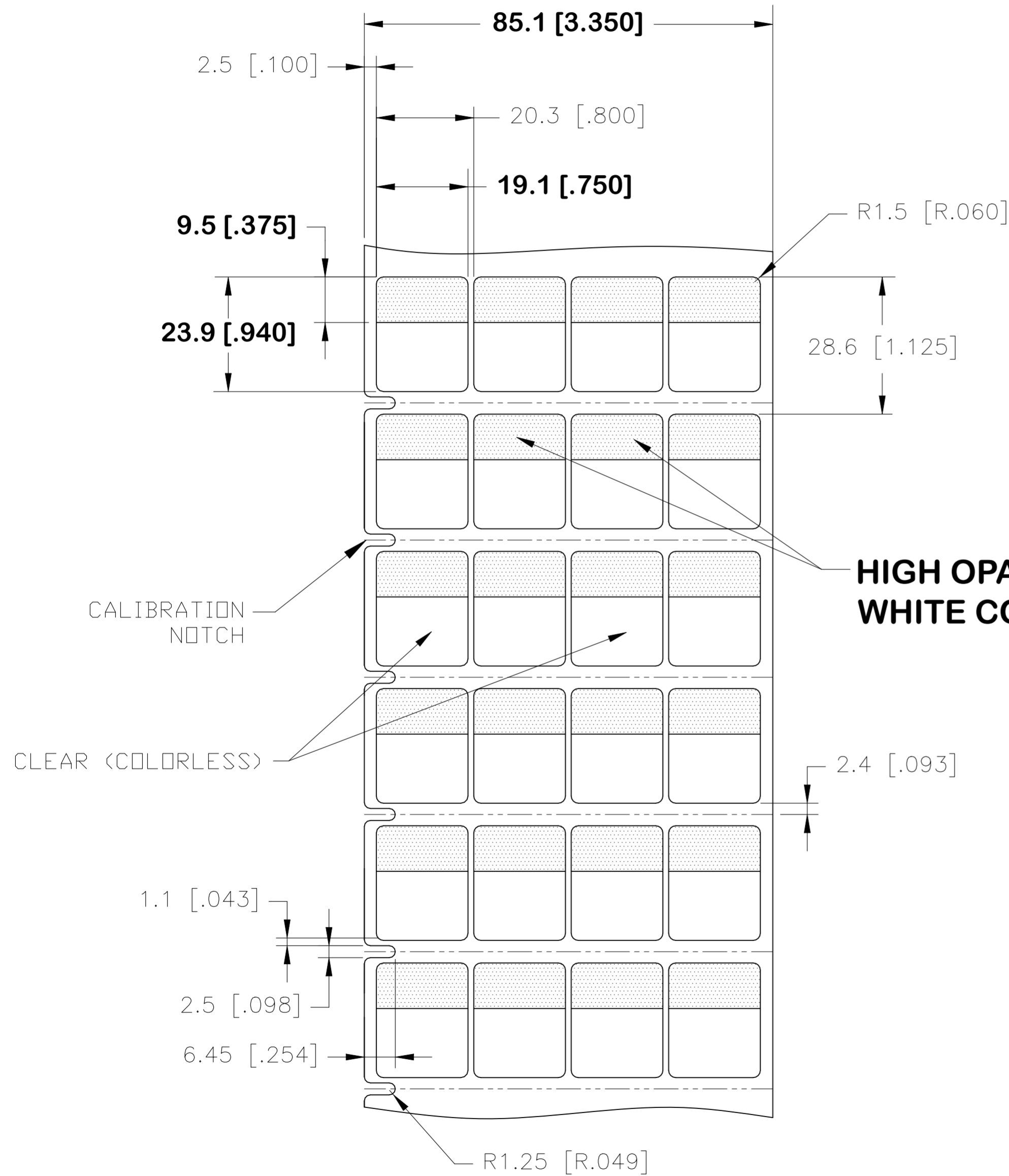

**HIGH OPACITY WHITE COLOR**

**OUTSIDE WOUND LABEL ACROSS: 4 PER ROLL QTY: 10000**

All dimensions in mm [Inch]

**TE PN: CN2895-000**

UL-MARKING AND LABELLING SYSTEMS	
PGCT2 - Flag Labels, Flag Tags, Wrap-around Labels & Related Products - Component	
PGCT8 - Flag Labels, Flag Tags, Wrap-around Labels & Related Products Certified for Canada - Component	
File: MH65661	Model N°: <b>SBP</b>

TOLERANCES mm [INCH]	
LABEL HEIGHT:	±0.3 [.012]
LABEL WIDTH:	±0.3 [.012]
WEB WIDTH:	±0.8 [.031]
VERTICAL REPEAT:	±0.8 [.031]*
HORIZONTAL REPEAT:	±0.8 [.031]*
PRINT POSITIONING:	±0.8 [.031]*
LEFT MARGIN:	±0.4 [.016]
QUANTITY:	-0 % +2 %
*NON ACCUMULATING	

THIS DRAWING IS A CONTROLLED DOCUMENT.	
DIMENSIONS:	TOLERANCES UNLESS OTHERWISE SPECIFIED:
mm [INCHES]	
	0 PLC ±
	1 PLC ±
	2 PLC ±
	3 PLC ±
	4 PLC ±
	ANGLES ±
MATERIAL:	FINISH:
SEE TABLE	GLOSSY

MATERIAL:	CLEAR VINYL
ADHESIVE TYPE:	ACRYLIC PERMANENT
LINEAR:	WHITE KRAFT
DWN:	18MAR2017
CHK:	18MAR2017
APVD:	18MAR2017
NAME:	
PRODUCT SPEC:	
APPLICATION SPEC:	
WEIGHT:	0.063g
SIZE:	A2
CAGE CODE:	00779
DRAWING NO:	C=SBP075094WE10
RESTRICTED TO:	
CUSTOMER DRAWING:	SCALE NTS SHEET 1 OF 1 REV F1