
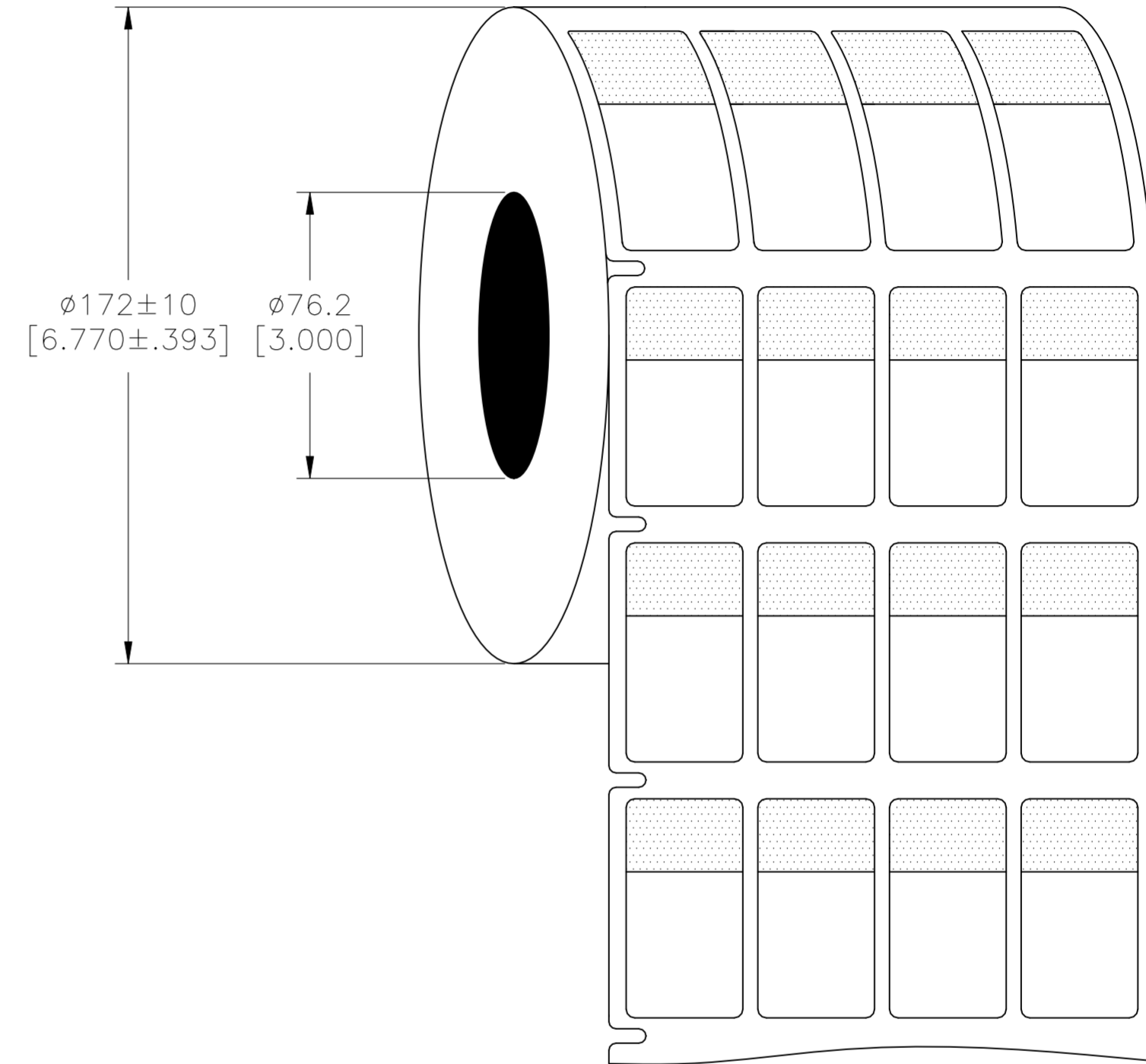


REVISIONS					
P	LTR	DESCRIPTION	DATE	DWN	APVD
F1		UL LABEL CHANGE	03JUL2024	GSK	DB

LABEL AND LINER DESIGN

PRESENTATION

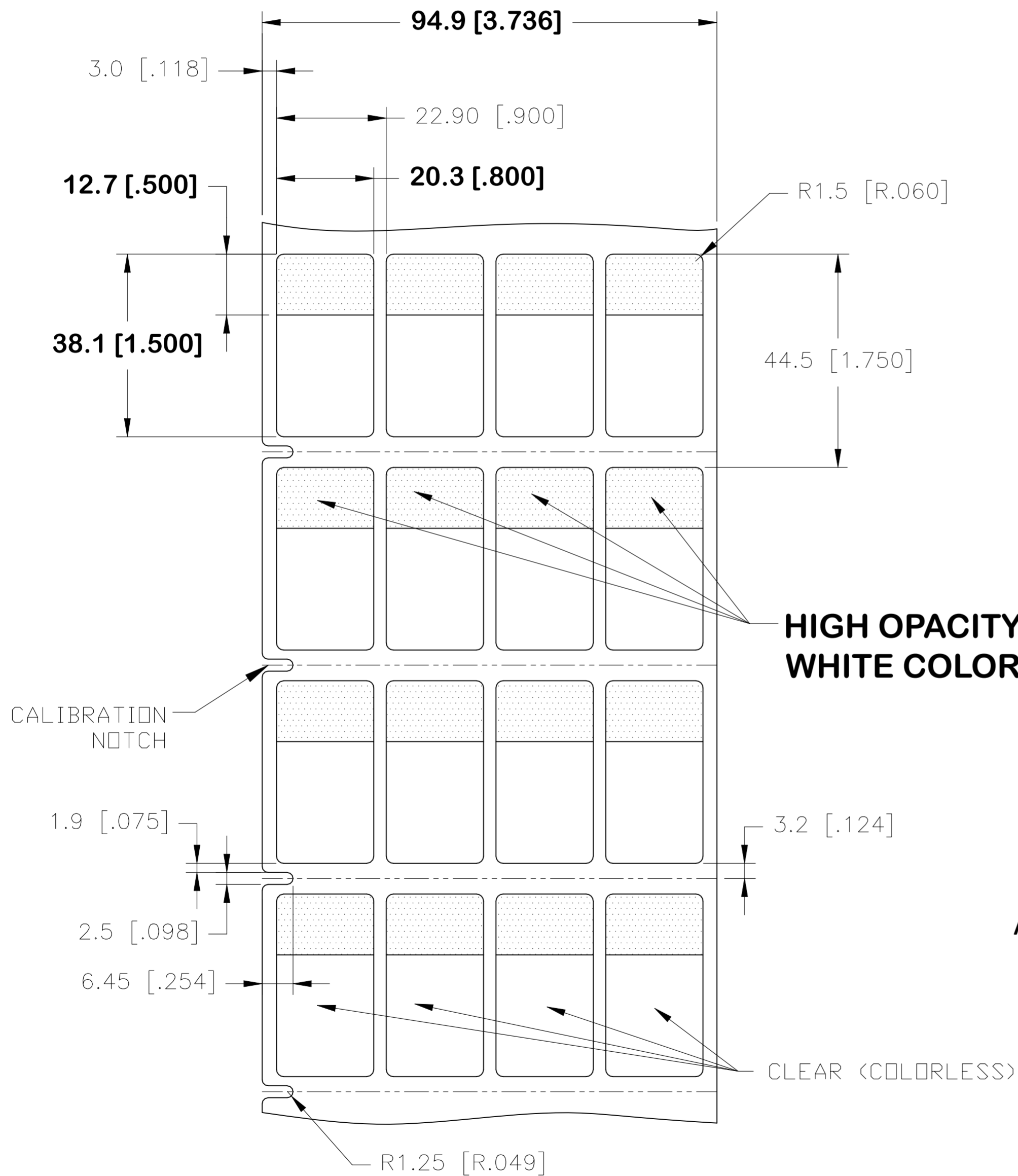

OUTSIDE WOUND LABEL ACROSS: 4 PER ROLL QTY: 10000

All dimensions in mm [Inch]

TE PN: CN2896-000

UL-MARKING AND LABELLING SYSTEMS	
PGCT2 - Flag Labels, Flag Tags, Wrap-around Labels & Related Products - Component	
PGCT8 - Flag Labels, Flag Tags, Wrap-around Labels & Related Products Certified for Canada - Component	
File: MH65661	Model N°: SBP

TOLERANCES mm [INCH]	
LABEL HEIGHT:	±0.3 [.012]
LABEL WIDTH:	±0.3 [.012]
WEB WIDTH:	±0.8 [.031]
VERTICAL REPEAT:	±0.8 [.031]*
HORIZONTAL REPEAT:	±0.8 [.031]*
PRINT POSITIONING:	±0.8 [.031]*
LEFT MARGIN:	±0.4 [.016]
QUANTITY:	-0 % +2 %
*NON ACCUMULATING	

DIMENSIONS: mm [INCHES]	
SEE TABLE	

THIS DRAWING IS A CONTROLLED DOCUMENT.	
DWN	GOPALAKRISHNA HV
CHK	D.BURGAT
APVD	D.BURGAT
PRODUCT SPEC	TIDS-211
APPLICATION SPEC	
MATERIAL	SEE TABLE
FINISH	GLOSSY

MATERIAL		CLEAR VINYL	
ADHESIVE TYPE	LINEAR	ACRYLIC PERMANENT	WHITE KRAFT

TE Connectivity	
NAME	SBP LABEL - WHITE
SIZE	20.3 x 38.1mm [0.8 x 1.5inch]
SIZE	A2
CAGE CODE	00779
DRAWING NO	C=SBP080150WE10
RESTRICTED TO	
WEIGHT	0.108g
CUSTOMER DRAWING	
SCALE	NTS
SHEET	1 of 1
REV	F1