



P	LTR	DESCRIPTION	DATE	DWN	APVD
F1		UL LABEL CHANGE	04JUL2024	GSK	DB

LABEL AND LINER DESIGN

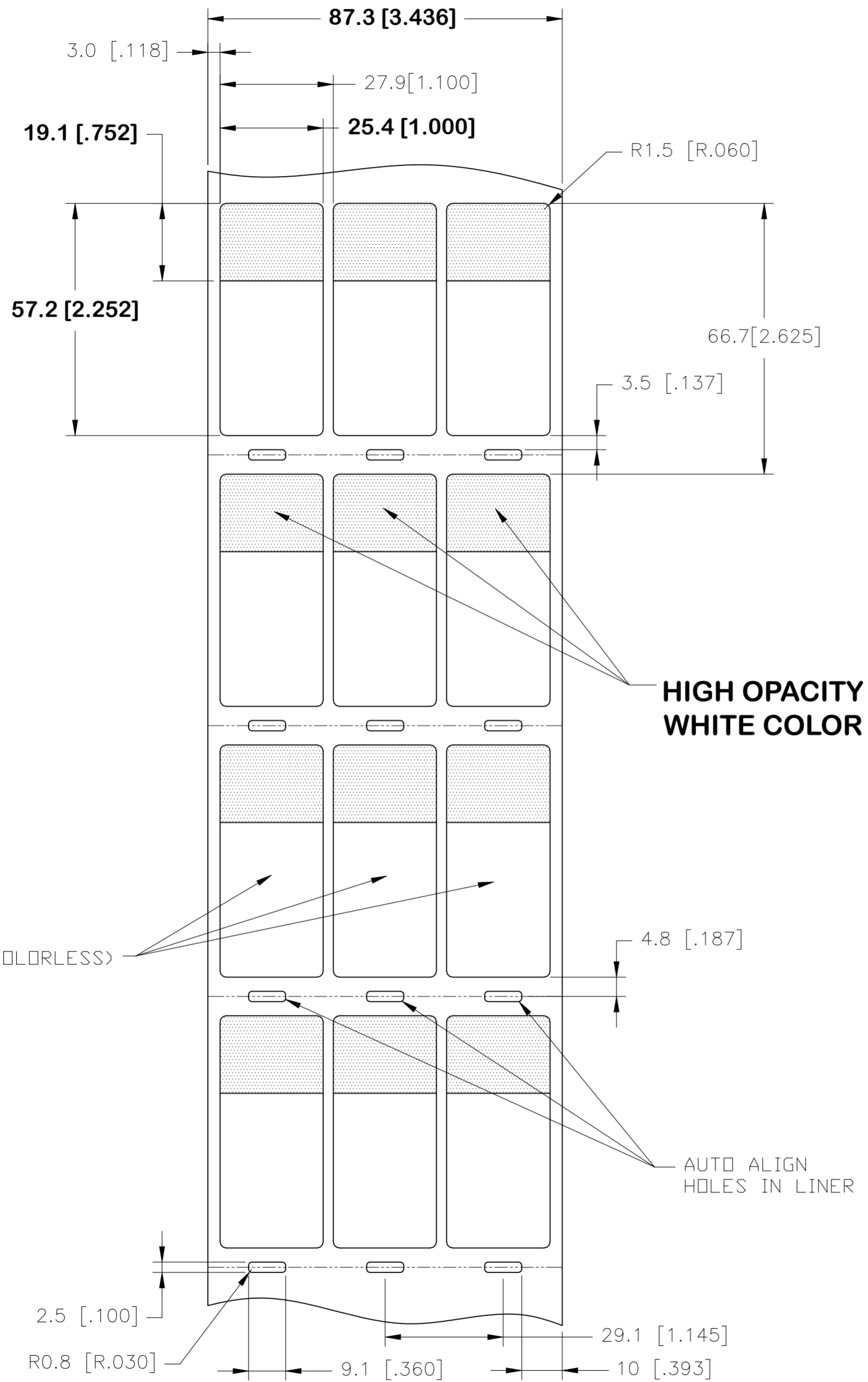

PRESENTATION

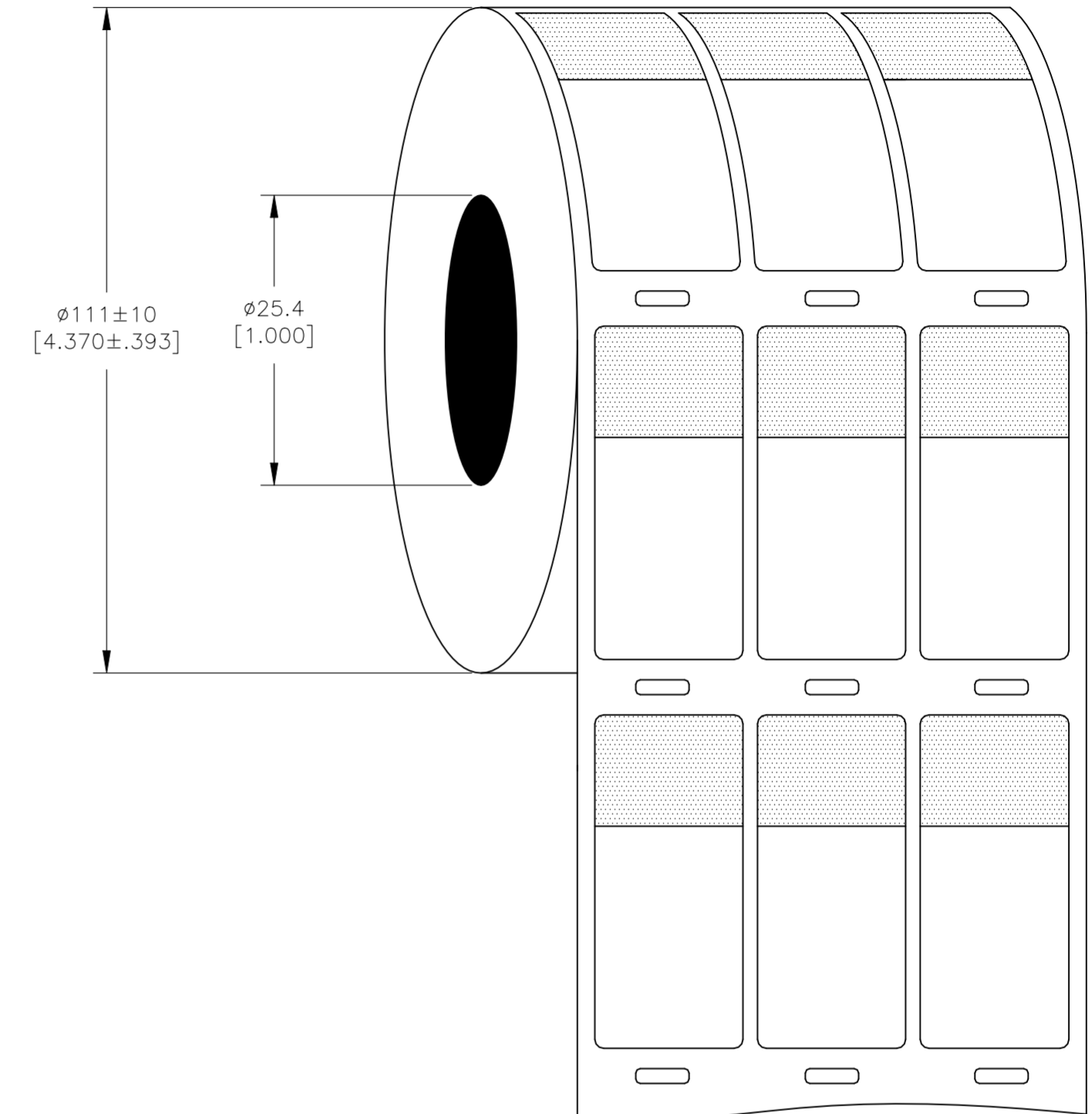

All dimensions in mm [Inch]

TE PN: CN9921-000

UL-MARKING AND LABELLING SYSTEMS	
PGCT2 - Flag Labels, Flag Tags, Wrap-around Labels & Related Products - Component	
PGCT8 - Flag Labels, Flag Tags, Wrap-around Labels & Related Products Certified for Canada - Component	
File: MH65661	Model N°: SBP

TOLERANCES mm [INCH]	
LABEL HEIGHT:	± 0.3 [.012]
LABEL WIDTH:	± 0.3 [.012]
WEB WIDTH:	± 0.8 [.031]
VERTICAL REPEAT:	± 0.8 [.031]*
HORIZONTAL REPEAT:	± 0.8 [.031]*
PRINT POSITIONING:	± 0.8 [.031]*
LEFT MARGIN:	± 0.4 [.016]
QUANTITY:	-0 % +2 %
*NON ACCUMULATING	

MATERIAL		CLEAR VINYL	
ADHESIVE TYPE		ACRYLIC PERMANENT	
LINEAR		WHITE KRAFT	
DWN 23FEB2017 GOPALAKRISHNA HV		TE Connectivity	
CHK 23FEB2017 D.BURGAT			
APVD 23FEB2017 D.BURGAT		NAME	
PRODUCT SPEC TIDS-211		SBP LABEL-WHITE-T200 PRINTER 25.4 x 57.2mm [1.00 x 2.25inch]	
APPLICATION SPEC		SIZE	RESTRICTED TO
WEIGHT 0.202g		A2 00779	—
CUSTOMER DRAWING		SCALE NTS	SHEET 1 OF 1
		REV F1	