

EKM-2050F-3D1-5S/U-6
Art.-Nr.: 393712-000 (JOR-88949)





Fuse Box for Lighting Application EKM 2050

According to DIN VDE 0660-505
 DIN 43628

- For installation in lighting columns with minimum diameter of 90 mm
- With door opening minimum 80 x 270 mm
- For outdoor application, not in arm's reach
- For 3 fuses D01 (E14) up to 16 A
- With 3 screw caps and 3 fuse inserts 6A
- With 5 sliding terminals
- Prewired with bars (N, L1, (L3), L2, PE(N))
- All metal parts corrosion protected (Ni-plated brass or stainless steel)
- Grey cover with screw
- Protection class II (with double or increased insulation)
- With ingress protection IP 54
- For 1 or 2 earth cables 4 mm² - 25 mm²
- or 3 earth cables 4 mm² - 16 mm²
- With easy adaptable cable sealing for 1-3 earth cables Ø 19 – 24 mm
- For 2 luminaire cables 3 x 1,5 mm² - 5 x 2,5 mm²
- 2 sealing grommets for luminaire cables Ø 8 – 14 mm
- Two additional luminaire cables can be routed towards the bottom of the box.

Standard Packing size: 1

circuit diagram:

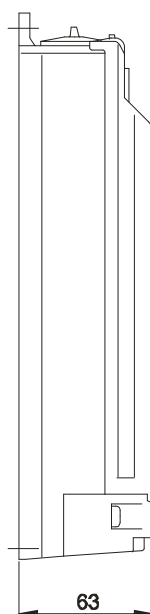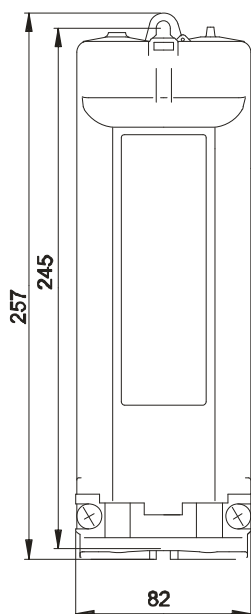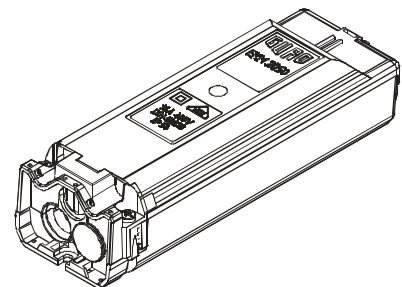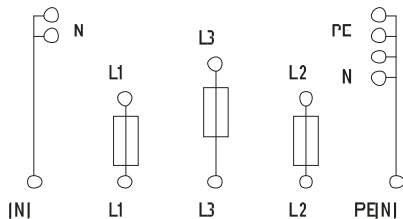

cable entry

