


REV. 0

DCO 63240

CUSTOMER DATA SHEET

COIL: @ 25°C	
SET	RESET
975 OHMS ±10%	975 OHMS ±10%
26.5 VDC NOMINAL VOLTAGE	26.5 VDC NOMINAL VOLTAGE
13.5 VDC MUST OPERATE	13.5 VDC MUST OPERATE

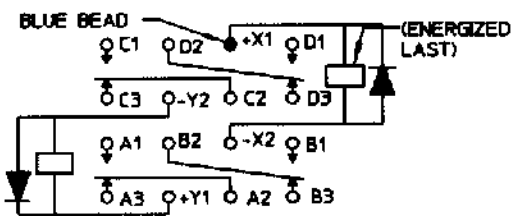

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE
100,000 OPERATIONS

DR. PBB 5-16-00

CK. *5/10/2000*

COMMUNICATIONS
INSTRUMENTS, INC.

3SBM1109A2

ENVIRONMENT:
 VIBRATION 10 Hz 3000 Hz 30 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 4 MS MAX.
CONTACT STABILIZATION 2.5 MS MAX.

CUST. QPL
 CUST. NO. M39016/35-003M

TYPE '3SBM' RELAY