


COIL: @ 25°C	
RESISTANCE	300 OHMS ± 10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	14.4 VDC
MUST RELEASE	1.8 VDC

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 20 g's
SHOCK	50 g's 11 MS. DURATION
TEMPERATURE	-55 °C TO +85 °C

NOTES: OPERATE & RELEASE TIME 10 MS MAX.
CONTACT BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

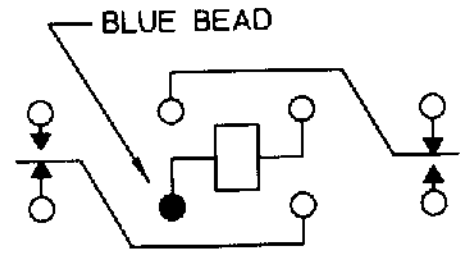

CONTACT RATING: 10 AMPS 28 VDC
5 AMPS 115 VAC, 400 HZ RESISTIVE
100,000 OPERATIONS

DR. R.B. 10/14/98 CK. 10/14/98

COMMUNICATIONS INSTRUMENTS, INC.

CUST. C. I. I. STD
CUST. NO. _____

TYPE 07 RELAY

A07B332AC1