
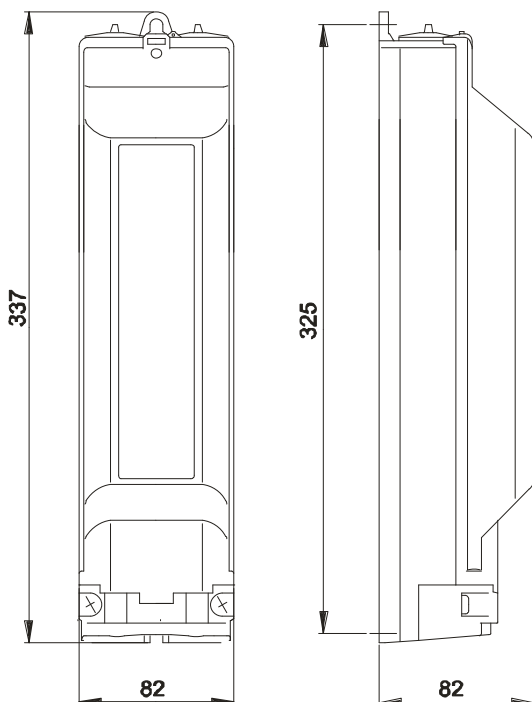


EKM-2051-5S-2R/D-DE01
Art.-Nr.: A16564-000 (JOR-89646)

Fuse box for lighting application EKM 2051 according to DIN 43628
 explanation SK (for installation in lighting columns)

- protection class II
 - ingress protection IP 54
 - minimum diameter 100 mm
 - door opening minimum 85 x 350 mm
 - l x w x h: 337 x 82 x 82 mm
 - transparent cover with snap lock
 - protection cover
 - 2 mounting rails TS 35 for application of installation devices
 - 5 sliding terminals
 - rail connection (brass rails, nickel-plated)
 - fully insulated PE- and N- output terminals
 - entry terminals for 2 cables to 4 x 25 mm² or 3 cables to 5 x 16 mm²
 - 2 pole clamping screws M 6 x 12
 - cable entry: cable clamp for 1 cable to 3 cables Ø 19-22 mm
 - output: 2 cable glands, cable Ø 8-14 mm
- Two additional luminaire cables can be routed towards the bottom of the box.

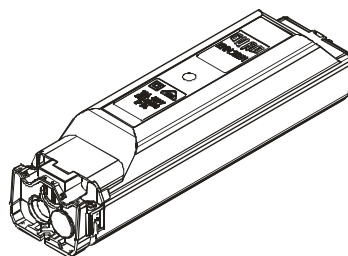

Cable entry

