


COIL: @ 25°C	
RESISTANCE	300 OHMS ± 10%
NOMINAL VOLTAGE	28.0 VDC
MUST OPERATE	13.0 VDC
MUST RELEASE	7.0 VDC MAX, 1.5 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 20 g's
SHOCK	50 g's 11 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES: OPERATE & RELEASE 10 MS MAX.
 OPERATE BOUNCE 2 MS MAX.
 RELEASE BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

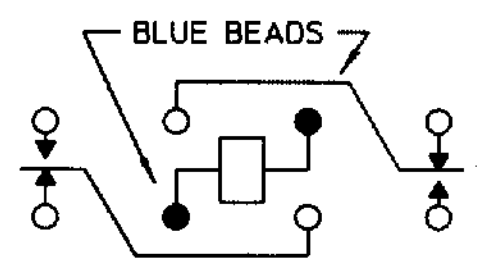

CONTACT RATING: 10 AMPS 28 VDC
115 VAC/400 HZ, 1 PHASE,
115/200 VAC, 3 PHASE RESISTIVE
100,000 OPERATIONS

DR. R.B. 4/14/94 CK. 4/14/94



CUST. OPL
 CUST. NO. MS27245-5

TYPE '07' RELAY

B07E932BC4-0262