
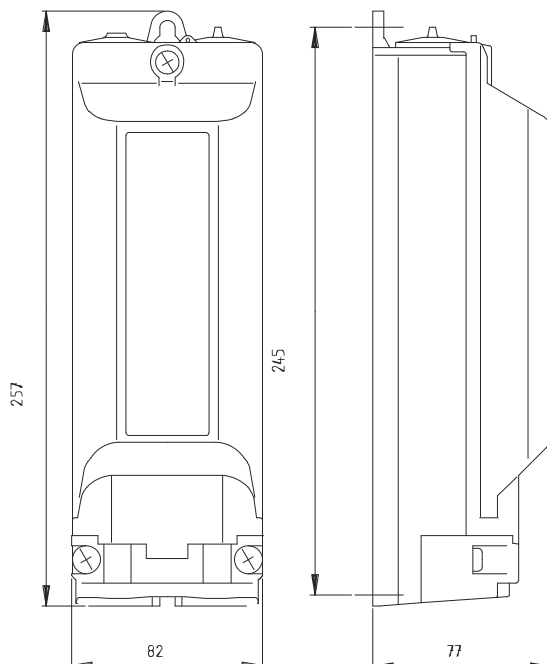


EKM-2050F-2D1FIX-4S/T
Art.-Nr.: C91264-000 (JOR-88932)

Fuse box for lighting application EKM 2050 according to DIN 43628

explanation SKF (for installation in lighting columns and outdoor application)

- protection class II
- ingress protection IP 54
- minimum diameter 98 mm
- door opening minimum 85 x 270 mm
- l x w x h: 257 x 82 x 77 mm
- grey cover with screw
- protection cover
- 2 fuse bases 16 A / D01-E 14,
- 2 screw caps E 14
- 4 sliding terminals
- 4-fan phase changes possible
- PEN- prewired
- rail connection (brass rails, nickel-plated)
- fully insulated PE- and N- output terminals
- entry terminals for 2 cable to 4 x 25 mm² or 3 cables to 4 x 16 mm²
- extension of cable break out area (80 mm)
- 2 pole clamping screws M 6 x 12
- cable entry: cable clamp for 1 cables to 3 cables Ø 19-22 mm
- output: 2 cable glands, cable Ø 8-14 mm

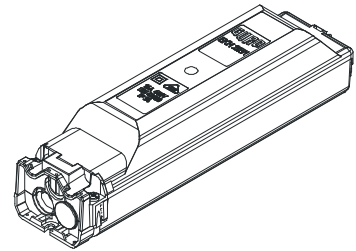

Cable entry

