



LOADBREAK ROTATABLE FEED THRU INSERT

15 kV AND 25 kV CLASS

KEY FEATURES

- High quality peroxide-cured EPDM insulation
- Includes grounding tabs to attach a drain wire to maintain dead-front safety
- Provides insulated, fully shielded, submersible connection
- Conforms to ANSI/IEEE Standard 386
- Yellow indicator ring confirms proper installation

TE Connectivity's (TE) Raychem 200A Loadbreak Rotatable Feed Thru Insert is available in 15 kV and 25 kV classes. The Feed Thru Insert connects to a universal bushing well and provides dual loadbreak bushing interfaces.


TE's Raychem Feed Thru Insert and elbow connectors provide fully shielded, submersible connection with conformance to IEEE Standard 386. These Feed Thru Inserts are therefore interchangeable with other manufacturers' products that also comply with this standard.

The yellow indicator ring provides installers a visual confirmation that the loadbreak elbow is properly seated on the Feed Thru Insert.


The torque limit ratchet feature prevents the bushing well stud from breaking during installation. The ratchet feature allows users to rotate the Feed Thru Insert 360° to orient the Feed Thru Insert in the desired position.

Customers can count on consistent, high quality products, driven by TE's proven innovation and backed by our extraordinary customer support.

Loadbreak Rotatable Feed Thru Insert

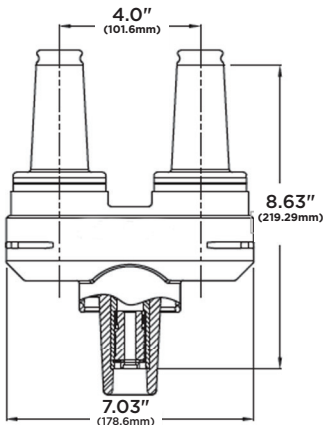

15 kV Portable Feed Thru Insert

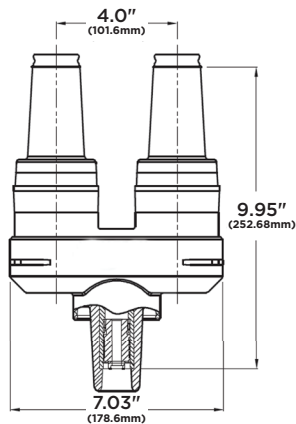

25 kV Portable Feed Thru Insert

LOADBREAK ROTATABLE FEED THRU INSERT WITH INDICATOR RING		
Voltage Ratings	15 kV	25 kV
Minimum Partial Discharge	11	19
Max. Rating Phase-to-ground	8.3	15.2
Max. Rating Phase-to-phase	14.4	26.3
AC 60 Hz 1 Minute Withstand (rms)	34	40
DC 15 Minute Withstand	53	78
BIL and Full Wave (Crest)	95	125

CURRENT RATINGS	
Description	A rms
Continuous Current	200
Switching Current	200
Fault-closure Current for 0.17s after 10 Switching Operations	10,000 symmetrical
Short-time Current for 0.17s	10,000 symmetrical
Short-time Current for 3.00s	3,500 symmetrical

ORDERING INFORMATION (Product Selection Information)			
Catalog Number	Product Description	Voltage Class	Current Rating
ELB-15-200-FTI	15kV Rotatable Feed Thru Insert	15kV	200 A
ELB-25-200-FTI	25kV Rotatable Feed Thru Insert	25kV	200 A

Kit Content: Rotatable Feed Thru Insert, Silicone Lubricant, Installation Instruction

te.com/energy

©2020 TE Connectivity Ltd. All Rights Reserved. EPP-3482-DDS-3/20

TE Connectivity, TE connectivity (logo), EVERY CONNECTION COUNTS, AMP, AMPACT, Axicom, Bowthorpe EMP, Crompton Instruments, Raychem, SIMEL, UTILUX are trademarks. Other logos, product and Company names mentioned herein may be trademarks of their respective owners. While TE has made every reasonable effort to ensure the accuracy of the information in this brochure, TE does not guarantee that it is error-free, nor does TE make any other representation, warranty or guarantee that the information is accurate, correct, reliable or current. TE reserves the right to make any adjustments to the information contained herein at any time without notice. TE expressly disclaims all implied warranties regarding the information contained herein, including, but not limited to, any implied warranties of merchantability or fitness for a particular purpose. The dimensions in this brochure are for reference purposes only and are subject to change without notice. Specifications are subject to change without notice. Consult TE for the latest dimensions and design specifications.

FOR MORE INFORMATION:
TE Technical Support Centers

USA/Canada:	+1 800-327-6996
Brazil:	+55 11-2103-6023
Mexico:	+52 55-1106-0800
South America:	+57 1-319-8962
Benelux:	+32 16-508-695
France:	+33 (0) 38-058-3210
Germany/Switzerland:	+49 (0) 89-608-9903
Italy:	+39 335-834-3453
Middle East/Africa:	+971 4-211-7020
Russia:	+7 495-790-790-2-200
Spain/Portugal:	+34 912-681-885
UK:	+44 08708-707-500
China:	+86 400-820-6015