


COIL: @ +25° C  
 RESISTANCE 1250 OHMS ± 10%  
 NOMINAL VOLTAGE 26.5-32.0 VDC  
 MUST OPERATE 14.0 VDC  
 MUST RELEASE 1.5 VDC

ENVIRONMENT:  
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's  
 SHOCK 100 g's 6 ± 1 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 4 MS MAX.  
 CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

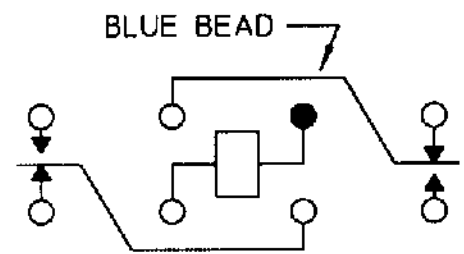

CONTACT RATING: LOW LEVEL TO 2A  
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 7/17/97 CK. 7/17/97

COMMUNICATIONS  
 INSTRUMENTS, INC.

CUST. C. I. I. STD.  
 CUST. NO.

TYPE 'HFW' RELAY

HFW1131D00