


REV. 0
DCO 17483

COIL: @ 25°C	
RESISTANCE	160 OHMS ±10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	6.4 VDC
MUST RELEASE	0.7 VDC

ENVIRONMENT:	
VIBRATION	10 Hz TO 3000 Hz @ 20 g's
SHOCK	100 g's 6±1 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

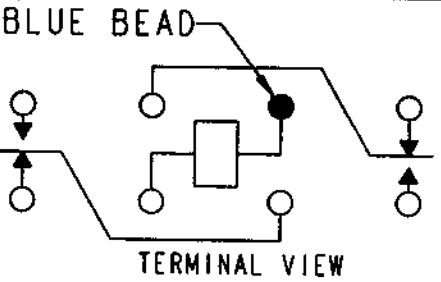

CONTACT RATING:	LOW LEVEL TO
	2A 28 VDC RESISTIVE
	100,000 OPERATIONS

DR. DS 1/15/02 CK.TIG 01-15-02



CUST. C.I.I. STD	"HFW" RELAY
CUST. NO. _____ REV. _____	

HFW1206G00