


REV. 0
DCO 143643

COIL: @ 25°C	
RESISTANCE	1560 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	17.0 VDC
MUST RELEASE	

ENVIRONMENT:	
VIBRATION	100 Hz TO 500 Hz @ 10 g's
SHOCK	30 g's 6 MS. DURATION
TEMPERATURE	-55 °C TO +85 °C
NOTES:	OPERATE TIME 4.0 MS MAX RELEASE TIME 3.0 MS MAX

CUSTOMER DATA SHEET

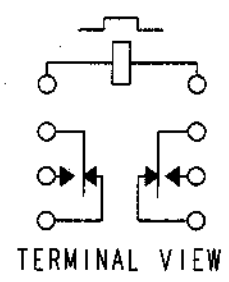

CONTACT RATING: LOW LEVEL TO
1A 28 VDC RESISTIVE 100,000 OPERATIONS

DR. ASB 3 SEPT 02 *CEP* 9/3/02



CUST. CII STD
CUST. NO. REV.

"HM" RELAY

HM1-26B