


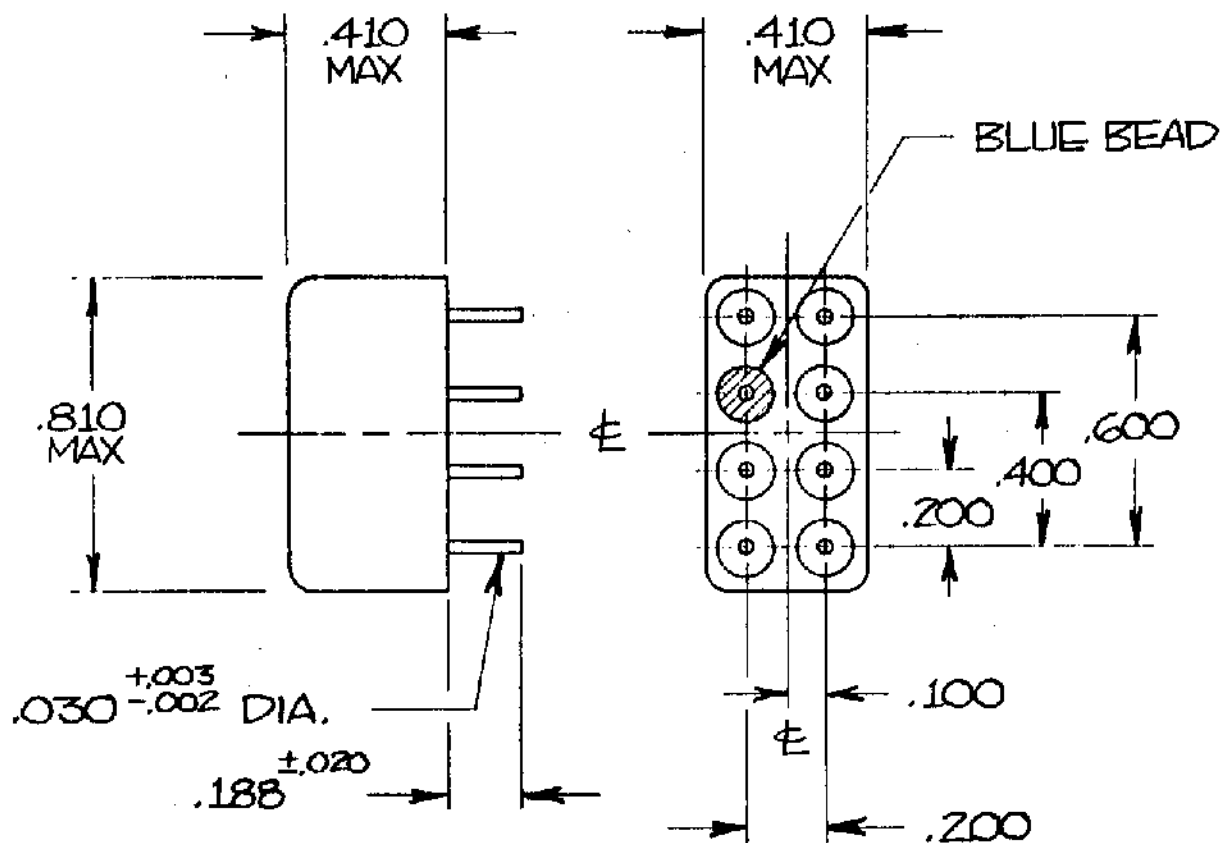

COIL: @ +25°C

RESISTANCE 2640 Ω ±10%

NOMINAL VOLTAGE 36.0 VDC

MUST OPERATE 18.0 VDC

MUST RELEASE 1.80 VDC

ENVIRONMENT:


VIBRATION 10 CPS TO 2500 CPS @ 20 g's

SHOCK 50 g's 6±1 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

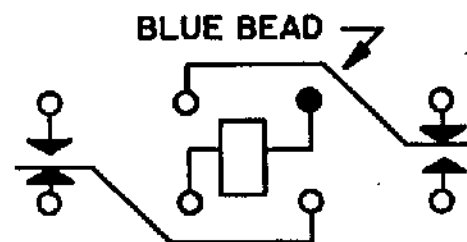

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC 100,000
OPERATIONS

DR. R.B. 12-14-90 CK. 12/14/90



Communications
Instruments, Inc.

CUST. C.I.I. STANDARD
CUST. NO. _____

TYPE HMS RELAY

HMS1201S006