


REV. 0
DCO 140839

| | |
|-----------------|----------------------------|
| COIL: @ 25°C | |
| RESISTANCE | 2300 OHMS ± 10% |
| NOMINAL VOLTAGE | 18.0 VDC |
| MUST OPERATE | 10.5 VDC |
| MUST RELEASE | 6.0 VDC MAX, 0.91 VDC MIN. |

| | |
|--------------|-----------------------------|
| ENVIRONMENT: | |
| VIBRATION | 10 CPS TO 3000 CPS @ 30 g's |
| SHOCK | 75 g's 6 MS. DURATION |
| TEMPERATURE | -65 °C TO +125 °C |

| | |
|--------|----------------------------|
| NOTES: | OPERATE TIME 4.0 MS MAX. |
| | RELEASE TIME 7.5 MS MAX. |
| | CONTACT BOUNCE 1.5 MS MAX. |

CUSTOMER DATA SHEET

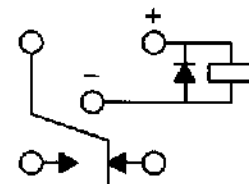

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 1/6/99 *CK JERRY C 4/6/99*

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M39016/25-032L

TYPE J1MSD RELAY

J1MSPD-18XL