


REV. 0  
DCO 143953

COIL: @ 25°C	
RESISTANCE	880 OHMS ±10%
NOMINAL VOLTAGE	18.0 VDC
MUST OPERATE	10.5 VDC
MUST RELEASE	6.0 VDC MAX., 0.91 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES: OPERATE TIME 2.0 MS MAX.	
RELEASE TIME 1.5 MS MAX.	
CONTACT STABILIZATION 2.0 MS MAX	

CUSTOMER DATA SHEET

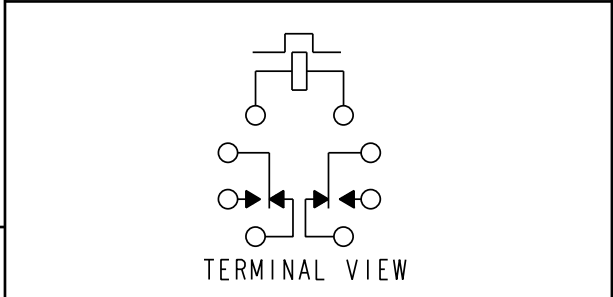

CONTACT RATING:	LOW LEVEL TO 1A
	28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 25OCT2004 CK. JERRY C. 10/25/04



CUST. QPL  
CUST. NO. M39016/9-023P REV.

"JMA" RELAY

JMAP-18XP