


REV. 0
DCO 140931

COIL: @ 25°C	
RESISTANCE	2500 OHMS ± 10%
NOMINAL VOLTAGE	30.0 VDC
MUST OPERATE	17.7 VDC
MUST RELEASE	10.0 VDC MAX, 1.50 VDC MIN

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	OPERATE TIME 2.0 MS MAX.
	RELEASE TIME 1.5 MS MAX.
	CONTACT STABILIZATION 2.0 MS MAX.

CUSTOMER DATA SHEET

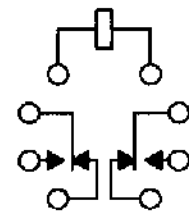

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 3/2/99 (CK) *ERRA* 3/2/99

 COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M39016/9-051P

TYPE JMA RELAY

JMAW-30XP