

REV. 0

DCO 141286

COIL: @ 25°C	
RESISTANCE	50 OHMS ±10%
NOMINAL VOLTAGE	5.0 VDC
MUST OPERATE	2.7 VDC
MUST RELEASE	1.4 VDC MAX, 0.22 VDC MIN.

ENVIRONMENT:


VIBRATION 10 CPS TO 3000 CPS @ 30 g's  
 SHOCK 75 g's 6 MS. DURATION.  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX

RELEASE TIME 15 MS MAX

CONTACT STABILIZATION 2.5 MS MAX

CUSTOMER DATA SHEET

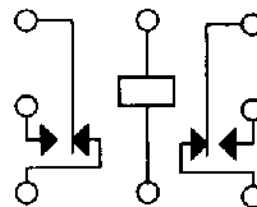

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1 AMP  
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 8/17/99 CK COPY 8/17/99



CUST. GPL  
 CUST. NO. M39016/17-037P REV.

JMGA RELAY

JMGAC-5PW