


REV, 1 8/25/98

COIL: @ 25°C	
RESISTANCE	39 OHMS ± 10%
NOMINAL VOLTAGE	5.0 VDC
MUST OPERATE	2.9 VDC
MUST RELEASE	1.4 VDC MAX, 0.23 VDC MIN.

CUSTOMER DATA SHEET

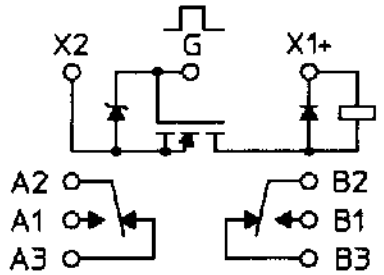

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

NOTES:	OPERATE TIME 2.5 MS MAX.
	RELEASE TIME 4.0 MS MAX.
	CONTACT BOUNCE 1.5 MS MAX.

DR. R.B. 12/19/97 *CK.* 8/25/98



CUST. QPL
 CUST. NO. M28776/6-007L

TYPE JMGAT RELAY

JMGAT-5LW