


REV. 0
DCO 143174

COIL: @ 25°C	
RESISTANCE	6500 OHMS ±10%
NOMINAL VOLTAGE	36.0 VDC
MUST OPERATE	20.0 VDC
MUST RELEASE	10.0 VDC MAX, 1.8 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES:	OPERATE TIME 4.0 MS MAX.
	RELEASE TIME 2.0 MS MAX.
	CONTACT STABILIZATION 2.0 MS MAX.

CUSTOMER DATA SHEET

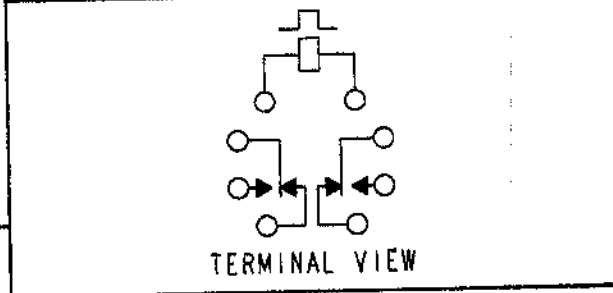

CONTACT RATING:	LOW LEVEL TO 1A
	28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 8/24/01 *OK Jerry 8/24/01*



CUST. NO.	OPL
	M39016/11-037P REV.

"JMS" RELAY

JMSC-36XP