


REV. 0  
DCO 143435

COIL: @ 25°C	
RESISTANCE	3300 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	14.0 VDC
MUST RELEASE	8.0 VDC MAX, 1.4 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES:	OPERATE TIME 4.0 MS MAX.
	RELEASE TIME 2.0 MS MAX.
	CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

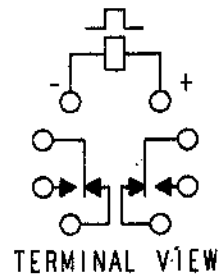

CONTACT RATING: LOW LEVEL TO 1A  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 1/30/02 *EX [Signature] 1/30/02*



CUST. OPL  
CUST. NO. M39016/11-023L REV.

"JMS" RELAY

JMSW-26XL