


COIL: 24 VDC NOMINAL	
WINDING #1	WINDING #2
630 OHMS ± 10% @ 25° C	630 OHMS ± 10% @ 25° C
14.0 VDC MUST OPERATE	14.0 VDC MUST OPERATE
ENVIRONMENT:	
VIBRATION <u>10</u> CPS TO <u>2000</u> CPS @ <u>30</u> g's	
SHOCK <u>100</u> g's <u>11</u> MS. DURATION	
TEMPERATURE <u>-65</u> °C TO <u>+125</u> °C	
NOTES: _____	
_____	
_____	

**CUSTOMER DATA SHEET**

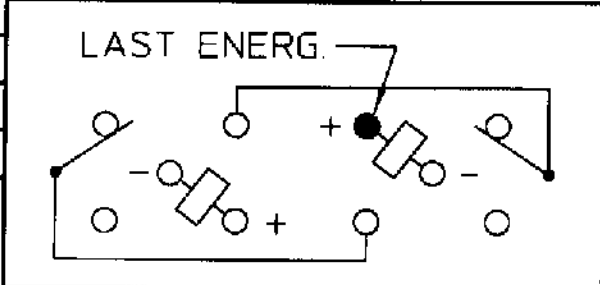

CONTACT RATING: 2 AMPS 30 VDC  
RESISTIVE 100,000 OPERATIONS

DR. R.B. 9/27/95 CK. JAK 9-27-95



UST. <u>P &amp; B</u>	TYPE "LS" RELAY
IST. NO. <u>SLG-11DA-24</u>	

**LS-9543**