


REV. 0  
DCO 143352

COIL: @ 25°C	
RESISTANCE	220 OHMS ±10%
NOMINAL VOLTAGE	9.0 VDC
MUST OPERATE	5.3 VDC
MUST RELEASE	3.0 VDC MAX, 0.54 VDC MIN.

CUSTOMER DATA SHEET

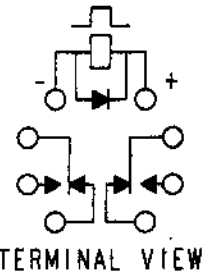

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

CONTACT RATING: LOW LEVEL TO 1A  
28 VDC RESISTIVE 100,000 OPERATIONS

NOTES: OPERATE TIME 2.0 MS MAX.  
RELEASE TIME 4.0 MS MAX.  
CONTACT BOUNCE 1.5 MS MAX.

DR. ASB 12/7/01 CK. *[Signature]* 12/07/01



CUST. C.I.I. STD  
CUST. NO. \_\_\_\_\_ REV. \_\_\_\_\_

"MAD"RELAY

MACD-9