


REV. 0
DCO 140851

COIL: @ 25°C
 RESISTANCE 1050 OHMS ± 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 15.9 VDC
 MUST RELEASE 9.4 VDC MAX, 1.36 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 100 g's
 SHOCK 150 g's 11 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX.
RELEASE TIME 4.0 MS MAX.
CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

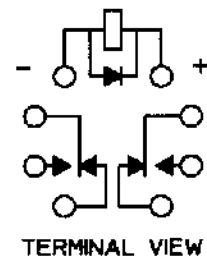

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 1/12/99 *(Signature)* 1/12/99

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I. STD.
 CUST. NO. _____

TYPE **MAVD RELAY**

MAVCD-26