

REV. 0

DCO 141109


COIL: @ 25°C	
RESISTANCE	1560 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	14.8 VDC
MUST RELEASE	9.5 VDC MAX. 1.8 VDC MIN.

ENVIRONMENT:

VIBRATION	10	CPS TO	3000	CPS @	30	g's
SHOCK	75	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

NOTES:	OPERATE TIME 2.0 MS MAX
	RELEASE TIME 4.0 MS MAX
	CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

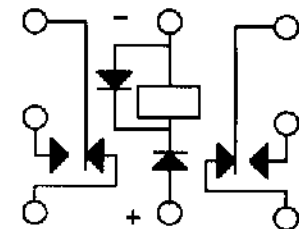

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 6/4/99 (CR) JERRY C 6/4/99



CUST. CII
CUST. NO. STANDARD

TYPE PRMGADD RELAY

PRMGACDD-26XW