


REV. 0
DCO 140790

COIL: @ 25°C	
RESISTANCE	3200 OHMS ± 10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	14.0 VDC
MUST RELEASE	1.4 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	OPERATE TIME 4.0 MS MAX
	RELEASE TIME 7.5 MS MAX
	CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

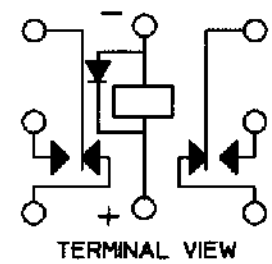

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS MIN

DR. R.B. 12/7/98 *[Signature]* 12/7/98



CUST. C. I. I.
CUST. NO. COTS STD.

TYPE PRMGSD RELAY

PRMGSCD-26XW