


REV. 0  
DCO 140826

COIL: @ 25°C  
 RESISTANCE 64 OHMS ± 10%  
 NOMINAL VOLTAGE 5.0 VDC  
 MUST OPERATE 2.9 VDC  
 MUST RELEASE 0.8 VDC MIN.

ENVIRONMENT:  
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's  
 SHOCK 75 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX  
RELEASE TIME 7.5 MS MAX  
CONTACT STABILIZATION 2.5 MS MAX.

CUSTOMER DATA SHEET

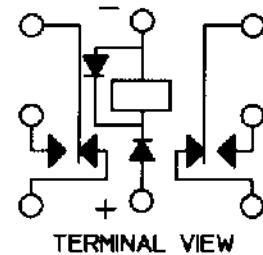

CONTACT RATING: LOW LEVEL TO 1 AMP  
28 VDC RESISTIVE 100,000 OPERATIONS MIN

DR. R.B. 12/18/98 *EK: JERRY C* 12/18/98

**COMMUNICATIONS**  
**INSTRUMENTS, INC.**

CUST. C. I. I.  
 CUST. NO. COTS STD.

TYPE "PRMGSCDD" RELAY

**PRMGSCDD-5YW**