


REV. 5
DCO 63333

COIL: @ 25°C	
RESISTANCE	390 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	14.0 VDC @ 25°C
MUST RELEASE	1.4 VDC @ 25°C

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 15 g's
SHOCK	100 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES:	OPERATE & RELEASE 7 MS MAX. (INCLUDING BOUNCE)

CUSTOMER DATA SHEET

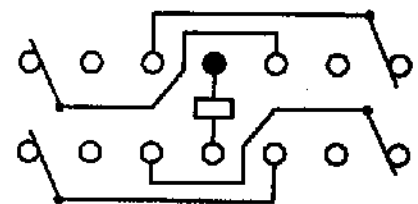

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
2 AMP 28 VDC RESISTIVE

DR. R.B. 1/29/93

CK. TLG 10-24-00

ICL Technologies
advanced control electronic solutions

CUST. OPL
CUST. NO. M39016/40-007 REV.

SR RELAY

SR-7607