

REV. 1


DCO 141326

COIL: @ 25°C	
RESISTANCE	650 OHMS ± 10%
NOMINAL VOLTAGE	18.0 VDC
MUST OPERATE	9.5 VDC
MUST RELEASE	5.6 VDC MAX, 1.0 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES: OPERATE & RELEASE 4 MS MAX.
BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

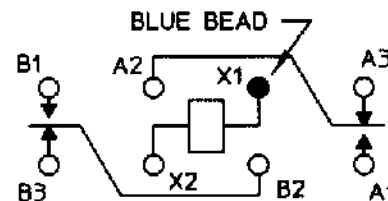

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE
50,000 OPERATIONS

DR. R.B. 1/20/98 CK. GAH 9/20/99



CUST. OPL
CUST. NO. M39016/13-077L REV.

3SBC RELAY

3SBC1542A2