

EKM-2050-2R/A

Art.-No.: E20858-000 (JOR-88904)

Empty housing EKM 2050

Type SK (inside poles)

for pole inner diameter ≥ 102 mm, for door opening $\geq 85 \times 300$ mm


2 pcs. DIN rail TS 35 for application of installation devices

High transparent cover with screw lock,

Degree of protection: IP 54

Feeder cable entry for 2 cables up to 4×25 mm² or 3 cables up to 5×16 mm²

Load cable entry: 2 rubber glands for cables 8 – 14 mm, additionally 2 cables downwards dia. $< 11,5$ mm.

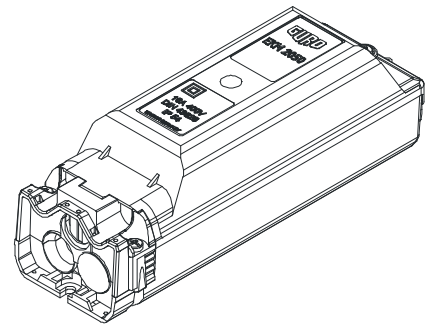

Kabelzugang

