

EKM-2035-4S6-1R
Art.-Nr.: EK6531-000

Fuse box for lighting application EKM 2035
According to DIN EN 61439

for installation in lighting columns

Protection class II

Ingress protection IP 44

Minimum pole diameter 110 mm

Door opening minimum 90 x 300 mm

l x w x h: 290 x 93,5 x 89 mm

Transparent cover with screw

1 mounting rail TS 35 for application of installation devices (like MCB; max 3 units)




Protection cover

4 sliding terminals with Allen key screws

sliding terminal connection (brass rails, nickel-plated)

cable entry: cable clamp for 1 cables to 2 cables 4 x 4 – 50 mm²
 for 3 cables 4 x 4 – 35 mm²

Load side: 2 sealing grommets for 1 cable 4-11 mm ea. or 4 wires 1,5 to 3 mm ea.

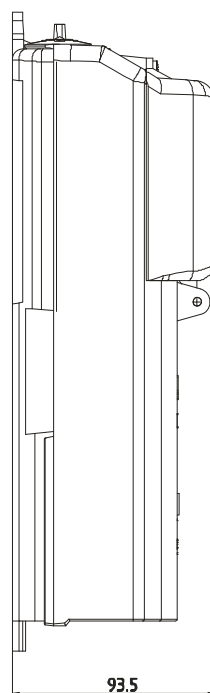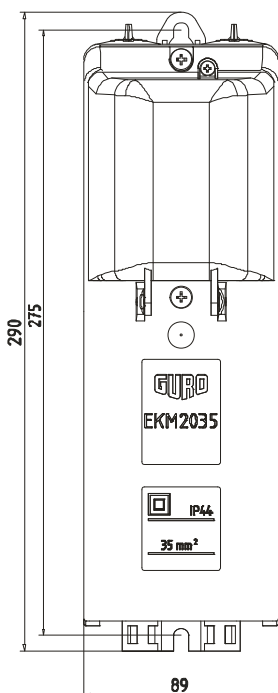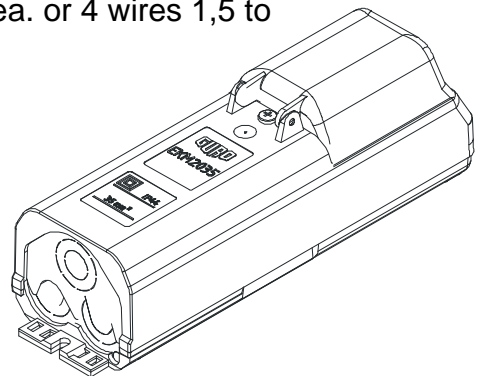

Cable entry

