


REVISIONS

P	LTR	DESCRIPTION	DATE	DWN	APVD
	1	NEW DRAWING	02SEP2020	KR	JV

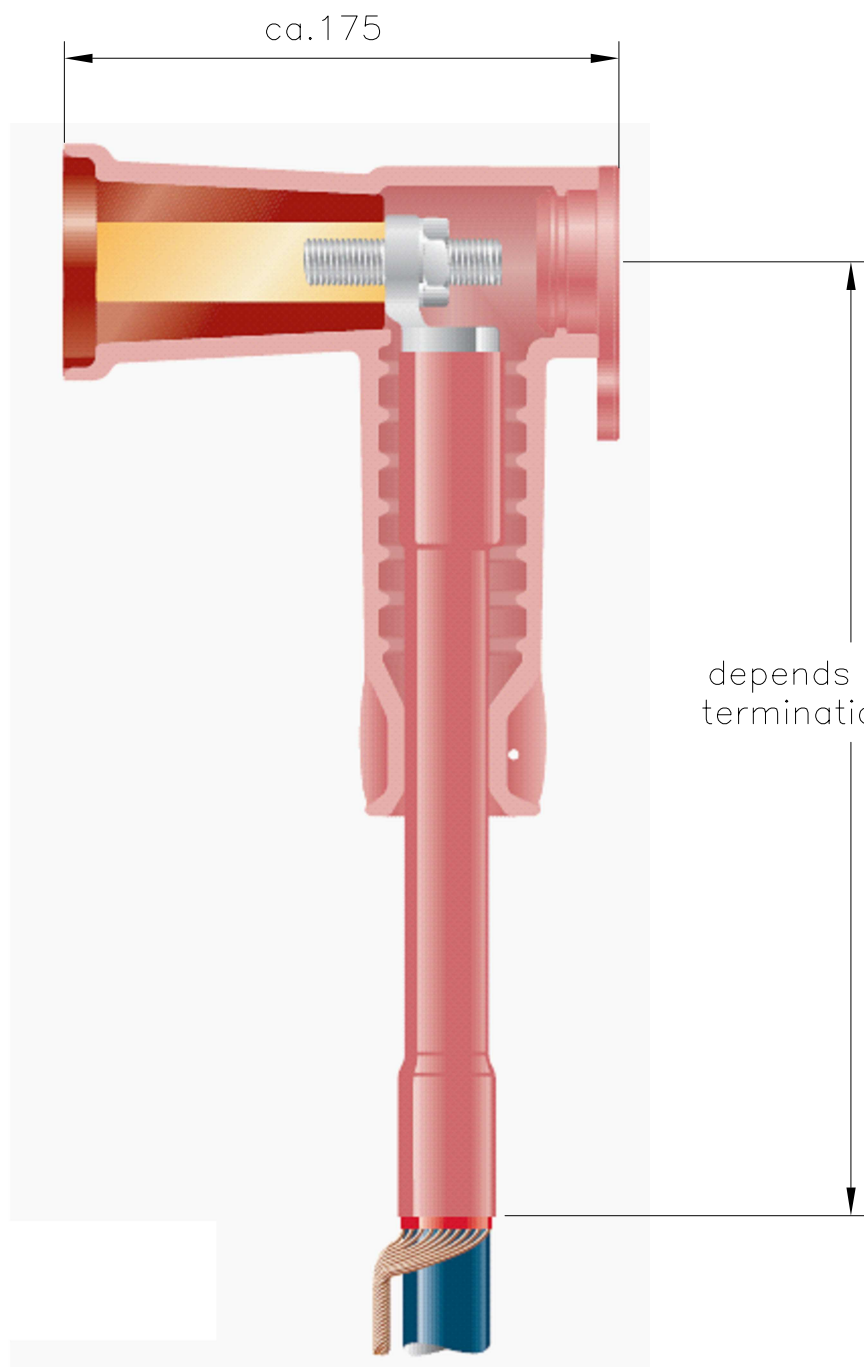

depends on the termination used

RICS adapter selection table with most common Raychem terminations

Cross section (mm ²)	Ordering description T-adapter	Termination for polymeric cables incl. Mechanical lugs
70-150	RICS-3133	IXSU-F3131-ML-2-17
95-240	RICS-3133	IXSU-F3131-ML-4-17
120-300	RICS-3133	IXSU-F3131-ML-5-17

Packaging

The insulating body, fixing bolts, terminal stud and cap are supplied in a 3-phase set complete with installation instruction. Cable terminations with lugs for M16 studs have to be ordered separately.

THIS DRAWING IS A CONTROLLED DOCUMENT.		DWN 02SEP2020 RAGHAVENDRA K.		
		CHK 02SEP2020 VALENCIA, JORDI		
DIMENSIONS: mm 		TOLERANCES UNLESS OTHERWISE SPECIFIED: 0 PLC ± - 1 PLC ± - 2 PLC ± - 3 PLC ± - 4 PLC ± - ANGLES ± -		NAME RICS-31XX
MATERIAL -		APVD 02SEP2020 RIVA, CARLOS PRODUCT SPEC - APPLICATION SPEC - WEIGHT -		SIZE A3
		CUSTOMER DRAWING		CAGE CODE 00779
		DRAWING NO RICS-31XX		RESTRICTED TO -
		SCALE NTS		SHEET 1 of 1
		REV 1		