

REV. C  
DCO 301387

BLUE BEAD


TOLERANCES  $\pm .010$ " - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C	
RESISTANCE	290 OHMS $\pm 10\%$
NOMINAL VOLTAGE	28 VDC
MUST OPERATE	13.5 VDC MAX.
COIL TRANSIENT SUPPRESSION: 42 VDC MAX.	
MUST RELEASE	5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	200 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES:	OPERATE, RELEASE 15 MS MAX.
	CONTACT STABILIZATION 2.5 MS MAX.
	CONTACT BOUNCE 1 MS MAX.
	CONTACT BREAK BOUNCE 0.1 MS MAX.

### CUSTOMER DATA SHEET

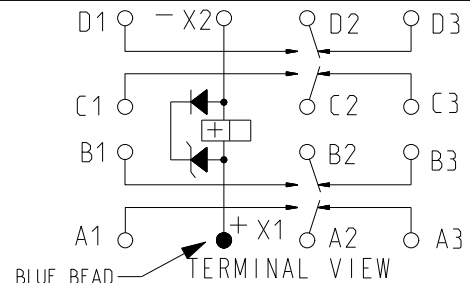

CONTACT RATING:	LOW LEVEL
10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE	
100,000 OPERATIONS	

DR. R.F. 21APR2011 CK. M.B. 26APR2011



CUST. QPL  
CUST. NO. M83536/16-020M REV. ----

TE NUMBER  
1-1617754-7

CII PART NUMBER  
FCA-410-1620M