

REV. C
DCO 301387


TOLERANCES $\pm .010$ " - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C
 RESISTANCE 290 OHMS $\pm 10\%$
 NOMINAL VOLTAGE 28 VDC
 MUST OPERATE 13.5 VDC MAX.
COIL TRANSIENT SUPPRESSION: 42 VDC MAX.
 MUST RELEASE 5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 Hz TO 3000 Hz @ 30 g's
 SHOCK 200 g's 6 MS. DURATION
 TEMPERATURE -70 °C TO +125 °C

NOTES: OPERATE, RELEASE 15 MS MAX.
CONTACT STABILIZATION 2.5 MS MAX.
CONTACT BOUNCE 1 MS MAX.
CONTACT BREAK BOUNCE 0.1 MS MAX.

CUSTOMER DATA SHEET

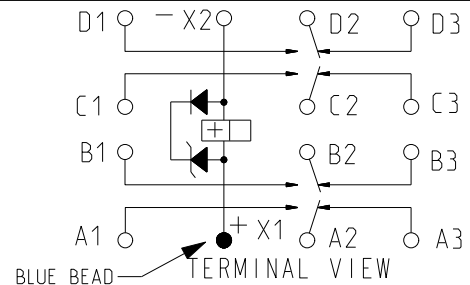

CONTACT RATING: LOW LEVEL
10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
100,000 OPERATIONS

DR. R.F. 21APR2011 CK. M.B. 26APR2011



CUST. QPL
 CUST. NO. M83536/16-022M REV. ----

TE NUMBER
2-1617754-1

CII PART NUMBER
FC A-410-1622M