


COIL: @ +25°C
 RESISTANCE 700 Ω ± 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 13.5 VDC
 MUST RELEASE 8.0 VDC MAX, 1.5 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 100 g's 6 MS.DURATION
 TEMPERATURE -65° °C TO +125° °C

NOTES: _____

CUSTOMER DATA SHEET

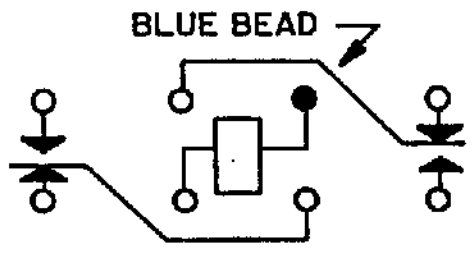

CONTACT RATING: 2 AMPS 28 VDC
RESISTIVE 100,000 OPERATIONS

DR. R.B. 10-30-90 CK. 10/30/90



CUST. QPL
 CUST. NO. M39016/6-142L

TYPE "HFW" RELAY

HFW 1201K 103