


REV. 0
DCO 143579

COIL: @ 25°C	
RESISTANCE	850 OHMS ±10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	7.8 VDC
MUST RELEASE	4.6 VDC MAX, 1.3 VDC MIN

ENVIRONMENT:		
* VIBRATION	10 Hz TO 3000 Hz @ 30 g's	
SHOCK	75 g's 6 MS. DURATION	
TEMPERATURE	-65 °C TO +125 °C	

NOTES: OPERATE 4.0 MS MAX.
RELEASE 7.5 MS MAX.
CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

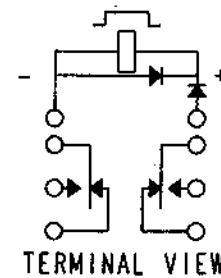

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. ASB 7 JUN 02 *CK* *EDD* 6/7/02



CUST. QPL
CUST. NO. M39016/21-044L REV.

"JMSDD" RELAY

JMSCDD-12XLS