

REV. 1
DCO 15852


COIL: @ 25°C	2000 OHMS ±10%
RESISTANCE	
NOMINAL VOLTAGE	18.0 VDC
MUST OPERATE	4.5 mADC
MUST RELEASE	0.50 mADC

ENVIRONMENT:

VIBRATION	10	CPS TO	2000	CPS @	20	g's
SHOCK	100	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

NOTES: OPERATE TIME 15 MS MAX
RELEASE TIME 10 MS MAX
(CATALOG IS 8 MS OPERATE, 4 MS RELEASE)

CUSTOMER DATA SHEET

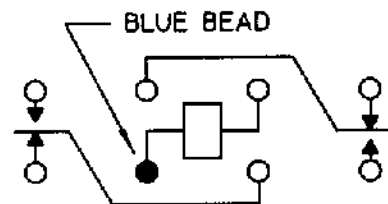

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
2 AMPS 30 VDC, 1 AMP 115 VAC 400 HZ
RESISTIVE 100,000 OPERATIONS

DR. R.B. 2/20/98 CK.Gg # 10/8/99



CUST. HI-G
CUST. NO. 2BK-2E-118 REV.

"SF" RELAY

SF6296H01