

COIL: @ 25°C	
RESISTANCE	50 OHMS ±10%
NOMINAL VOLTAGE	5.0 VDC
MUST OPERATE	2.7 VDC
MUST RELEASE	1.4 VDC MAX, 0.22 VDC MIN.


ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	OPERATE TIME 2.0 MS MAX
	RELEASE TIME 1.5 MS MAX
	CONTACT TIME 1.5 MS MAX.

CUST.	C.I.
CUST. NO.	STANDARD REV.


SMGA RELAY

CUSTOMER DATA SHEET

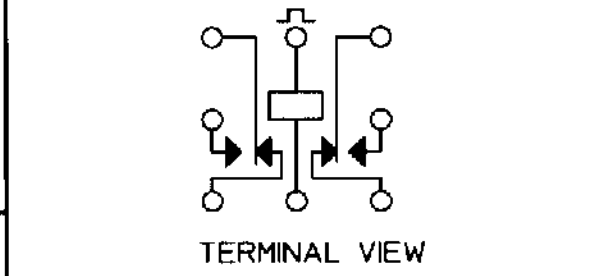

CONTACT RATING:	LOW LEVEL TO 1 AMP
	28 VDC RESISTIVE 100,000 OPERATIONS

 DR. B.D. 11/17/99 CK. *[Signature]* 11/17/99



SMGA-5